

Optomechanics

Mounting Basics

Optical Rails

Mirror Mounts

Lens Mounts

Filter Mounts

Rotation Post Mounted

Adapters

V-Mounts

Apertures & Iris Diaphragms

Lens Tubes


Cage Systems

Black Flocked Self-Adhesive Paper

In many applications where the light path travels through an enclosed area, image contrast can suffer due to stray light reaching the focal plane. Applying a flat black paint to the inside helps, but a textured flocked paper is a much better light trap. This flocked paper is a black, self adhesive material made from many fine fibers. When viewed from low angles, it absorbs virtually 100% of light that strikes it. The fibers will not shed like some velvets and felts do.



- Economical solution for stray light elimination
- Self-adhesive for easy application
- Fine fibers absorb virtually all stray light

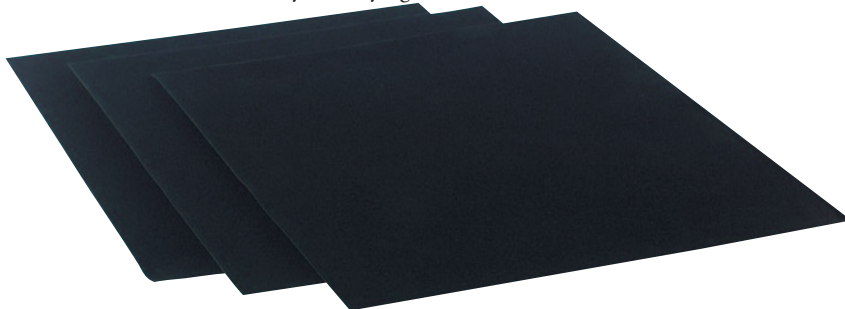


ITEM#	\$	£	€	¥	DESCRIPTION
BFP1	\$27.00	£20.25	€28,35	¥4,590	Black Flock Paper 30"x30" 2 Sheets

Black Hardboard

- Heavy Duty Construction Board - 5mm Thick
- Cuts with Utility Knife
- Build Light Tight Boxes with Our 2" Wide Black Masking Tape (Shown Below)
- Custom Sizes Available

ITEM#	\$	£	€	¥	DESCRIPTION
TB4	\$58.00	£43.50	€60,90	¥9,860	3 Sheets, 24" x 24"

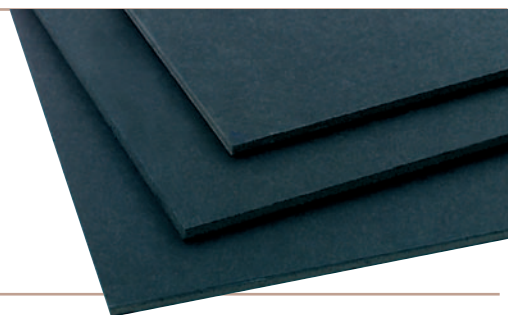

Black Masking Tape



BLACK MASKING TAPE

General purpose black masking tape, often used along with our black rubberized fabric to form temporary light tight coverings for sensitive equipment.

ITEM#	\$	£	€	¥	DESCRIPTION
T137-0.5	\$5.89	£4.42	€6,18	¥1,001	1/2" x 60 Yd. (12.7mm x 55 Meter) Roll
T137-1.0	\$7.87	£5.90	€8,26	¥1,338	1.0" x 60 Yd. (25mm x 55 Meter) Roll
T137-2.0	\$13.90	£10.42	€14,60	¥2,363	2" x 60 Yd. (50mm x 55 Meter) Roll

Black-Out Material



BLACK RUBBERIZED FABRIC

Black rubberized fabric provides an easy method for protecting light-sensitive equipment. The rubberized coating prevents light from penetrating through the weave of the fabric.

- Not intended for use in laser curtain applications
- Double layered for extremely sensitive applications



ITEM#	\$	£	€	¥	SIZE
BK5	\$42.00	£31.50	€44,10	¥7,140	60" Wide x 3 Yd in Length (1.5 Meters x 2.7 Meters)