

Fiber Optics

Passive Components

Collimation Packages

FiberBench

Optical Switches

Rackbox Systems

Connectors/
Termination Tools

Single Mode Fiber

Rare Earth Doped

Polarization
Maintaining Fiber

Photonic
Crystal Fiber


Multimode Fiber:
Graded Index

Multimode Fiber:
Step Index

Plastic Optical Fiber


Fiber Optic Stripping Tool

STRONGLY RECOMMENDED
"Best Choice" Stripping Tool

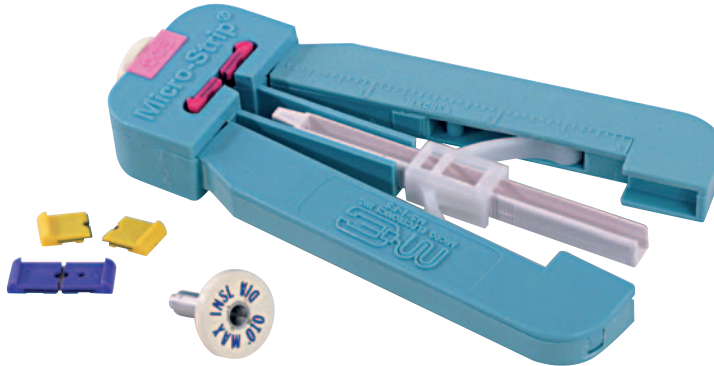

- Foolproof, No-Nick Design
- Fast, Reliable Fiber Stripping
- Self-Aligning Blade Set Assures Concentric Scoring of Buffer or Coating

Single Mode, Multimode, and Polarization
Maintaining Fibers

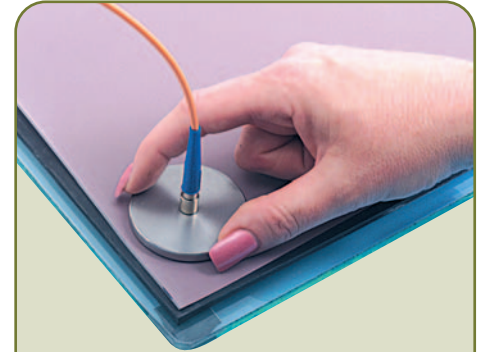

Fiber Polishing Kits

Complete set of accessories
for polishing and connectorizing fibers.

See Page 1048

Tool Selection

- Note your CLADDING and COATING* diameters along with their respective high side tolerances.
- Look down the sixth column of the table below for your fiber size.
- With your fiber size identified in the chart below, scan across to the corresponding CLADDING RANGE & COATING* RANGE columns. Ensure that your fiber dimensions plus the high side tolerances fall within the range listed; if they do, then refer to the corresponding ITEM# to place your order. If the maximum fiber dimensions fall outside the range shown, order the next larger tool.

Standard Tool Selection

ITEM#	\$	£	€	RMB	TYPICAL FIBER CLADDING/COATING	CLADDING RANGE	COATING* RANGE
T04S10	\$ 66.60	£ 42.00	€ 61.90	¥ 636.00	80µm / 200µm	65 - 80µm	150 - 250µm
T05S10	\$ 66.60	£ 42.00	€ 61.90	¥ 636.00	100µm / 200µm	85 - 120µm	150 - 250µm
T06S13	\$ 66.60	£ 42.00	€ 61.90	¥ 636.00	125µm / 250µm	125 - 135µm	250 - 343µm
T08S13	\$ 66.60	£ 42.00	€ 61.90	¥ 636.00	140µm / 250µm	125 - 175µm	250 - 343µm
T08S40	\$ 66.60	£ 42.00	€ 61.90	¥ 636.00	125µm / 900µm	125 - 175µm	889 - 1016µm
T12S16	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	240µm / 400µm	235 - 280µm	343 - 407µm
T12S18	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	240µm / 400µm	235 - 280µm	407 - 457µm
T12S21	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	230µm / 500µm	235 - 280µm	457 - 533µm
T12S25	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	250µm / 600µm	235 - 280µm	533 - 635µm
T16S31	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	325µm / 650µm	335 - 380µm	635 - 787µm
T18S31	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	400µm / 730µm	385 - 430µm	635 - 787µm
T21S31	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	430µm / 730µm	435 - 500µm	635 - 787µm
T23S46	\$ 64.00	£ 40.30	€ 59.50	¥ 611.20	500µm / 1000µm	505 - 550µm	1016 - 1168µm
T28S46	\$ 65.90	£ 41.50	€ 61.30	¥ 629.30	630µm / 1040µm	605 - 680µm	1016 - 1168µm
M34S52	\$ 65.10	£ 41.00	€ 60.50	¥ 621.70	750µm / 1250µm	755 - 830µm	1168 - 1321µm
M37S46	\$ 65.10	£ 41.00	€ 60.50	¥ 621.70	860µm / 1080µm	835 - 900µm	1016 - 1168µm
M44S63	\$ 65.10	£ 41.00	€ 60.50	¥ 621.70	1035µm / 1400µm	905 - 1050µm	1397 - 1600µm
M44S67	\$ 65.10	£ 41.00	€ 60.50	¥ 621.70	1400µm / 1600µm	905 - 1050µm	1600 - 1702µm
M54S76	\$ 65.10	£ 41.00	€ 60.50	¥ 621.70	1250µm / 1850µm	1055 - 1350µm	1778 - 1930µm
M63S86	\$ 77.70	£ 49.00	€ 72.30	¥ 742.00	1550µm / 2000µm	1390 - 1600µm	2057 - 2184µm

*Coating refers to the jacket, buffer, or coating that is being removed.

