

19" Equipment Racks


Standard 19" EIA Rack

- 7' x 19" Floor-Standing Equipment Rack
- Heavy-Duty, 3" Wide, Vertical Channels
- Weight Capacity is 750 lbs (Load Must be Evenly Distributed)
- #12-24 Tapped Mounting Holes in a 5/8", 5/8", 1/2" Repeating Hole Pattern
- Side Holes Allow Multiple Racks to be Bolted Together
- Universal Design is Imperial and Metric Compatible




RK3884

These heavy-duty, 19" equipment racks are an ideal lab organizer. Manufactured from aluminum U-channels and angle extrusions, the weight capacity is 750 lbs, which should be distributed evenly along its height.

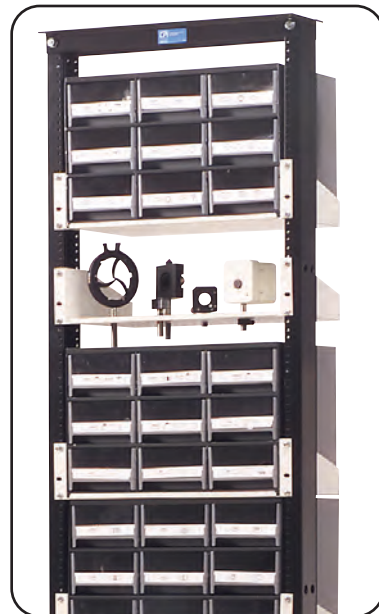

| ITEM# | \$ | £ | € | RMB | DESCRIPTION |
|--------|-----------|----------|----------|------------|------------------------------|
| RK3884 | \$ 235.70 | £ 163.40 | € 209,30 | ¥ 1,990.30 | 7' x 19" Wide Equipment Rack |

19" Slide-Out Rackboard

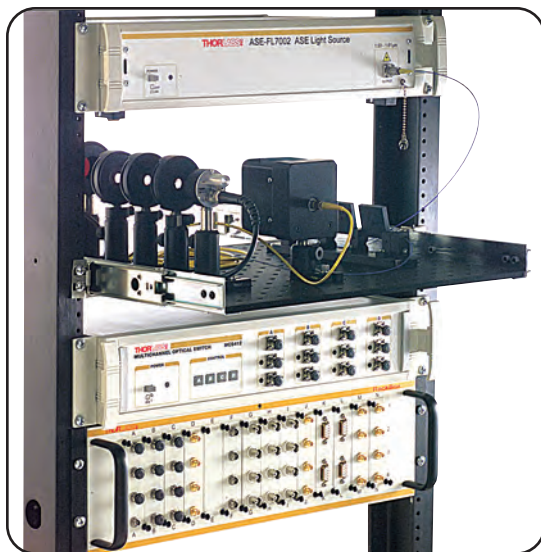

- Mounts Optomechanics within 19" Racks
- Low-Profile Optical Breadboard Shelf (1/2")
- Supports up to 50 lbs
- Mounts to Both Front and Back Rack Channels for Extra Rigidity
- Ball Bearing Slides



RK5006

These slideout rack boards (1/4"-20 on 1" centers or M6 x 1.0 on 25 mm centers) allow optical systems to be built within instrumentation racks.

This combination allows integration of plug-and-play instruments using the full array of Thorlabs' optical benchtop components.

1/4"-20 (M6 x 1.0) Tapped Holes on 1" (25 mm) Centers

| ITEM# | METRIC# | \$ | £ | € | RMB | DESCRIPTION |
|--------|----------|-----------|----------|----------|------------|-------------------------|
| RK5006 | RK5006/M | \$ 305.00 | £ 211.50 | € 270,80 | ¥ 2,575.50 | 19" Slide-Out Rackboard |