

FINAL INSPECTION REPORT


High Precision Pinhole

Item #: P1000HD
 SN: 0027404

Pinhole Diameter: $1000 \pm 10 \mu\text{m}$
 Circularity Tolerance: $\geq 95\%$
 Housing: $\varnothing 0.5''$
 Material: 316 Stainless Steel
 Coating: None/Black

Parameter	Value
Diameter	998 μm
Circularity	99%

Pinhole Image

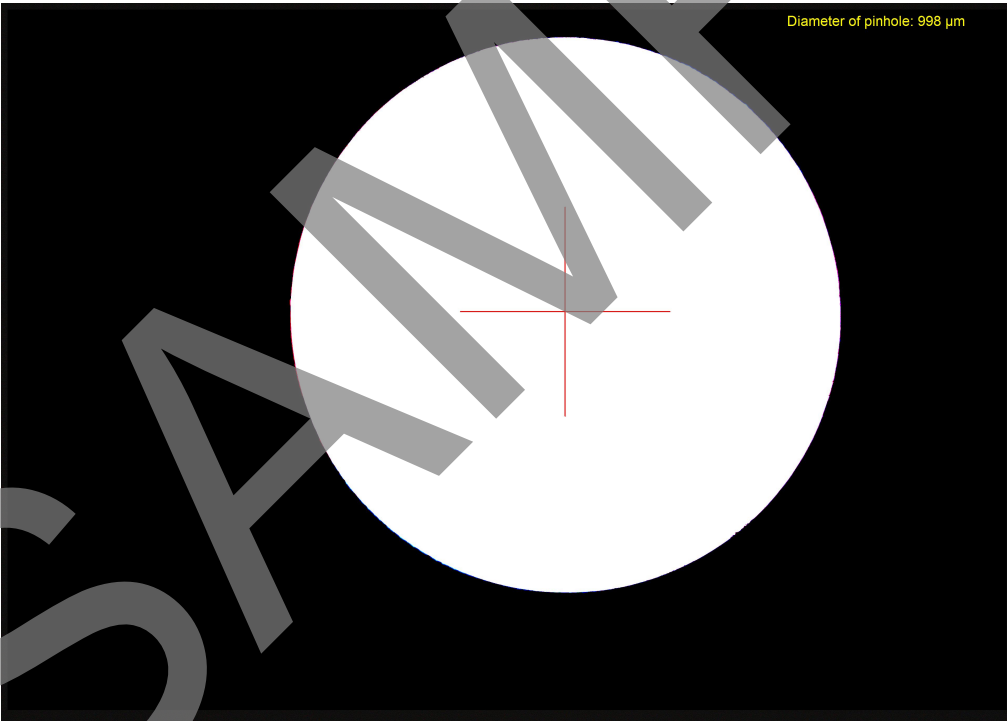

Verified by: DC